



# EA164DB-8-41 (1/2")インパクトソケット

- 6ポイント
- 差込角 1/2"

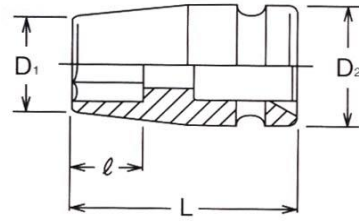

	mm	D1(mm)	D2(mm)	l(mm)	L(mm)	適用ピン	適用リング	重量(g)	
	EA164DB-8	8	14.5	25	6	38	EA164AA-3.5A	EA164A-19	85
取扱中止	<del>EA164DB-9</del>	<del>9</del>	<del>15.7</del>	<del>25</del>	<del>7</del>	<del>38</del>			85
	EA164DB-10	10	17	25	7	38			85
取扱中止	<del>EA164DB-11</del>	<del>11</del>	<del>18.2</del>	<del>25</del>	<del>8</del>	<del>38</del>			85
	EA164DB-12	12	19.5	25	9	38			85
	EA164DB-13	13	20.7	25	10	38			85
	EA164DB-14	14	22	25	10	38			85
	EA164DB-15	15	23.2	30	11	38	EA164AA-3.5B	EA164A-24	130
	EA164DB-16	16	24.5	30	11	38			130
	EA164DB-17	17	25.7	30	12	38			130
	EA164DB-18	18	27	30	13	38			130
	EA164DB-19	19	28.2	30	13	38			125
	EA164DB-20	20	29.5	30	13	38			127
	EA164DB-21	21	30.7	30	14	38			120
	EA164DB-22	22	32	30	14	38			130
	EA164DB-23	23	33.2	30	14	38			130
	EA164DB-24	24	34.5	30	14	38			135
	EA164DB-25	25	35.7	30	14	38			135
	EA164DB-26	26	37	30	14	38			160
	EA164DB-27	27	38.2	30	16	40			160
取扱中止	<del>EA164DB-28</del>	<del>28</del>	<del>39.5</del>	<del>30</del>	<del>16</del>	<del>40</del>			170
	EA164DB-29	29	40.7	30	17	42	190		
	EA164DB-30	30	42	30	17	42	190		
取扱中止	<del>EA164DB-31</del>	<del>31</del>	<del>43.2</del>	<del>30</del>	<del>17</del>	<del>42</del>	213		
	EA164DB-32	32	44.5	30	18	42	216		
	EA164DB-33	33	45.7	30	19	46	260		
	EA164DB-34	34	47	30	19	46	263		
	EA164DB-35	35	48.2	30	19	46			
	EA164DB-36	36	49.5	30	20	46	285		
	EA164DB-38	38	52	30	20	53			
	EA164DB-41	41	55.7	30	21	55	411		

(例)

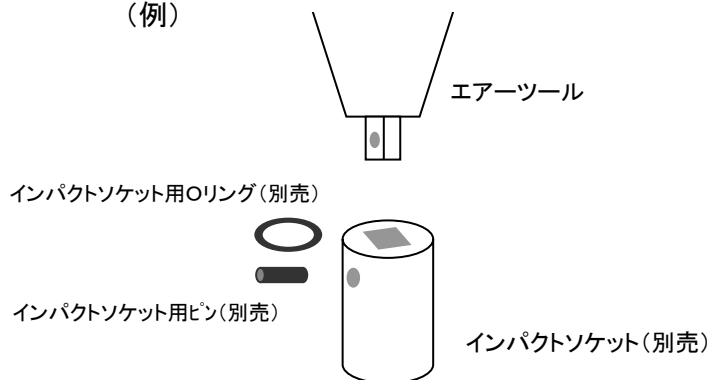

必ずインパクトソケット用ピン、Oリングを併用してください。