


EA164EB-17-60 (3/4")インパクトソケット

- 6ポイント
- 差込角 3/4"

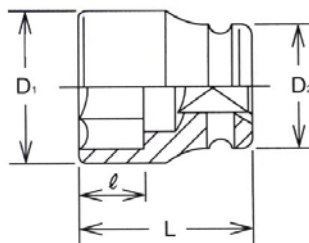


品番	mm	D1(mm)	D2(mm)	l(mm)	L(mm)	適用ピン	適用リング	重量(g)
EA164EB-17	17	30	44	12	50	EA164AA -5.5A	EA164A -36	355
EA164EB-18	18	31.3	44	13	50			372
EA164EB-19	19	32.5	44	13	50			360
EA164EB-20	20	33.8	44	14	50			375
EA164EB-21	21	35	44	15	50			374
EA164EB-22	22	36.3	44	15	50			373
EA164EB-23	23	37.5	44	16	50			373
EA164EB-24	24	38.8	44	16	50			370
EA164EB-25	25	40	44	16	50			374
EA164EB-26	26	41.3	44	16	50			378
EA164EB-27	27	42.5	44	16	50			375
EA164EB-28	28	43.8	44	16	50			383
EA164EB-29	29	45	44	18	53			412
EA164EB-30	30	46.3	44	18	53			410
EA164EB-31	31	47.5	44	18	53			426
EA164EB-32	32	48.8	44	19	53			428
EA164EB-33	33	50	44	20	55			470
EA164EB-34	34	51.3	44	20	55			490
EA164EB-35	35	52.5	44	20	55			494
EA164EB-36	36	53.8	44	20	55			498
EA164EB-37	37	55	44	20	55			526
EA164EB-38	38	56.3	44	20	57			558
EA164EB-39	39	57.5	44	20	57			579
EA164EB-40	40	58.8	44	20	57			598
EA164EB-41	41	60	44	22	57			572
EA164EB-42	42	61.3	44	22	57			617
EA164EB-43	43	62.5	44	23	62			720
EA164EB-44	44	63.8	44	23	62			761
EA164EB-45	45	65	44	23	62			757
EA164EB-46	46	66.3	44	23	62			755
EA164EB-47	47	67.5	54	23	62	805		
EA164EB-50	50	71.3	54	30	62	930		
EA164EB-52	52	73.8	54	29	62	1011		
EA164EB-54	54	76.3	54	29	62	1035		
EA164EB-55	55	77.5	54	29	62	1056		
EA164EB-58	58	81.3	54	31	65	1163		
EA164EB-60	60	83.8	54	31	65	1215		

廃番

廃番


(例)

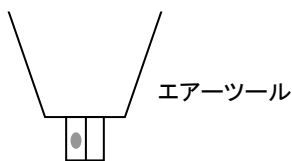

インパクトソケット用リング(別売)



 インパクトソケット用ピン(別売)



インパクトソケット(別売)

必ずインパクトソケット用ピン、リングを併用してください。

