


# EA164EK-17~55 (3/4")インパクト用ディープソケット

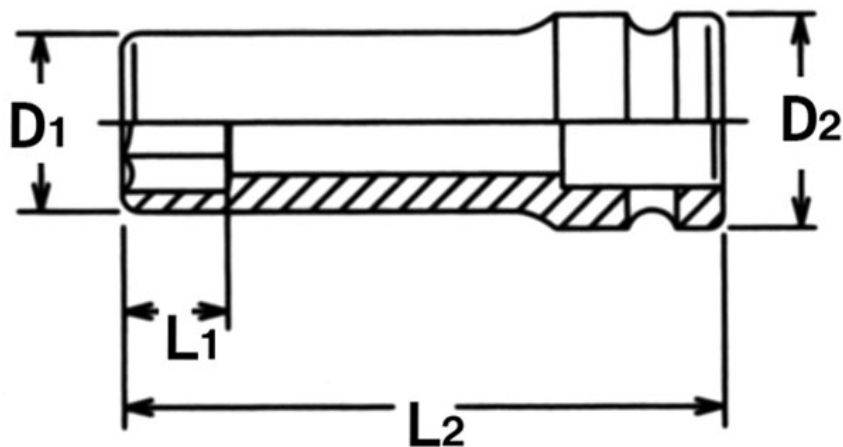

品番	六角対辺	D1	D2	L1	L2(全長)	重量(g)	
EA164EK-17	17	30	44	17	100	544	
EA164EK-18	18	31.3		18		642	
EA164EK-19	19	32.5		19		655	
EA164EK-20	20	33.8		20		680	
EA164EK-21	21	35		21		700	
EA164EK-22	22	36.3		22			
EA164EK-23	23	37.5		23		720	
EA164EK-24	24	38.8		24		705	
EA164EK-25	25	40		25		715	
EA164EK-26	26	41.3		26		760	
EA164EK-27	27	42.5		27		765	
EA164EK-28	28	43.8		28		800	
EA164EK-29	29	45		29		835	
EA164EK-30	30	46.3		30		840	
EA164EK-31	31	47.5		31		815	
EA164EK-32	32	48.8		32		875	
EA164EK-33	33	50		33		920	
EA164EK-34	34	51.3		34		950	
EA164EK-35	35	52.5		35		980	
EA164EK-36	36	53.8		36		960	
EA164EK-37	37	55		37		970	
EA164EK-38	38	56.3		38		990	
EA164EK-40	40	58.8				1060	
EA164EK-41	41	60				1120	
EA164EK-42	42	61.3				1153	
EA164EK-43	43	62.5		1200			
EA164EK-46	46	66.3		1305			
EA164EK-50	50	71.3		54		61	1469
EA164EK-55	55	77.5				59	1620

単位: (mm)

- 6ポイント
- 差込角…3/4"

