


EA617YE - 101 - 114 (3/8)ロングソケット

クロム合金鋼
差込角 3/8"
12ポイント

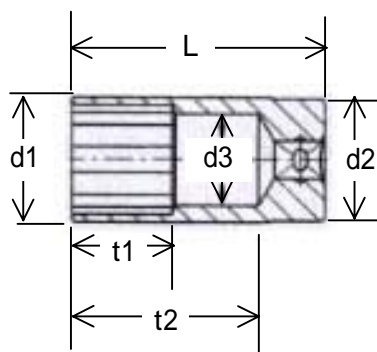

	対辺 (mm)	サイズ (mm)						重量 (g)
		d1	d2	d3	L	t1	t2	
EA617YE - 101	1/4"	9.7	16.5	5.2	54	9	42.5	33
EA617YE - 102	5/16"	11.7	16.5	7	54	9	42.5	35
EA617YE - 103	3/8"	13.7	16.5	8.4	54	20	42.5	45
EA617YE - 104	7/16"	15.7	16.5	10	54	20	40.7	53
EA617YE - 105	1/2"	18	17.5	11.5	54	20	40.2	64
EA617YE - 106	9/16"	20.2	19	13.1	60	25	45.8	66
EA617YE - 107	19 / 32"	20.6	19	14	60	25	48.2	84
EA617YE - 108	5/8"	21.7	19.5	15	60	25	47.9	81
EA617YE - 109	11/16"	23.4	21.5	16.3	65	30	52.5	114
EA617YE - 110	3/4"	25.2	23	18	65	30	52	137
EA617YE - 111	13/16"	27.2	25	19.4	65	30	51.6	130
EA617YE - 112	7/8"	28.7	26.5	21	65	30	51.2	184
EA617YE - 113	15/16"	31.5	29	22.6	65	30	50.7	195
EA617YE - 114	1"	33	31	24.2	65	30	50.2	205