


EA618BR-6~-27
 (3/8"ディープソケット)

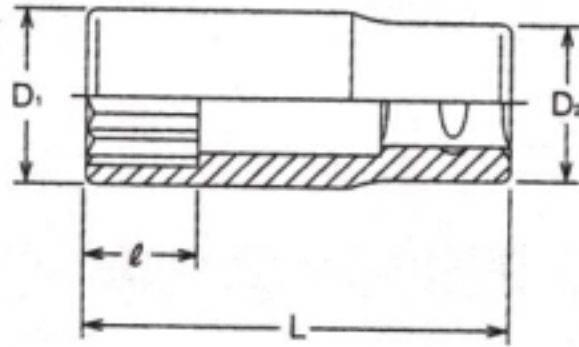

- 差込角 3/8"
- 12ポイント

	対辺	D1	D2	\varnothing	L	重量(g)
BR-6	6	9.9	17.3	7	55	45
BR-7	7	10.6	17.3	8	55	44
BR-8	8	12	17.3	9	55	45
BR-9	9	13	17.3	10	55	47
BR-10	10	14.5	17.3	11	55	52
BR-11	11	16	17.3	12	55	55
BR-12	12	16.8	17.2	13	55	58
BR-13	13	18	17	14	55	57
BR-14	14	20	18	16	55	68
BR-15	15	21	20	16	55	78
BR-16	16	22	20	17	55	79
BR-17	17	23.5	22	18	55	96
BR-18	18	24.5	23	19	55	96
BR-19	19	25	24	20	55	102
BR-20	20	26	25	21	65	129
BR-21	21	27	26	22	65	140
BR-22	22	29	28	23	65	166
BR-23	23	30	29	24	65	185
BR-24	24	31	30	25	65	193
BR-27	27	35	32.5	28	65	250

(mm)