


EA618CL-8 ~ -38 (1/2")ソケット

12角ソケット
差込角 1/2"

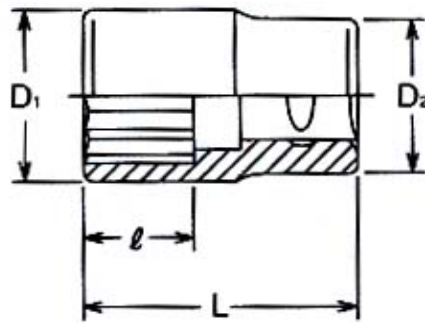

	サイズ(mm)	D1(mm)	D2(mm)	l (mm)	L (mm)	重量(g)
CL-8	8	13.2	21	8	36	44
CL-9	9	13.8	21	8.5	37	43.5
CL-10	10	15.3	21	9	37	45
CL-11	11	16.5	21	9.5	37	46
CL-12	12	17.8	21	10	37	47
CL-13	13	19	22	10.5	37	53
CL-14	14	20.3	22	11	37	56
CL-15	15	21.5	22	11.5	37	52
CL-16	16	22.8	22	12	37	62
CL-17	17	24	23	12.5	37	69
CL-18	18	25	24	13	37	74
CL-19	19	26.5	25	14	38	89
CL-20	20	27.8	26	15	38	92
CL-21	21	29	27	15.5	38	102
CL-22	22	30	28	16	40	113
CL-23	23	31.5	29	16.5	40	128
CL-24	24	32.8	30	17	42	140
CL-25	25	34	31	18	42	164
CL-26	26	35	32	19	42	165
CL-27	27	36.5	33	19.5	43	196
CL-28	28	37.8	34	20	43	198
CL-29	29	39	35	20.5	43	190
CL-30	30	40	36	22	46	222
CL-31	31	41.5	37	22.5	46	257
CL-32	32	42.8	38	23	46	250
CL-33	33	44.2	39	24	47	275
CL-34	34	45.2	40	24	47	315
CL-35	35	46.2	40	24	47	317
CL-36	36	47.2	41	24	47	336
CL-38	38	49.2	43	24	47	380