

Product Data Sheet



P 263/20-75R

EAN 4047526040109

ID 40105

Wheel with pneumatic tyres, with pressed steel rim

Wheels:

Pneumatic tyre with tube, outstandingly high operational comfort, exceptionally high floor preservation, PAH conform acc. to EU directive 2005/69/EC.

Tread colours: black

Wheel centre/rim:

Made of pressed steel, with tubular steel hub, zinc-plated, blue-passivated, Cr6-free. Tyre mounted on rim.

Wheel centre colour: silver



Rolling resistance

■ ■ ■ □ □ Good

Operating noise

■ ■ ■ ■ ■ Excellent






 

 

 



Floor surface preservation


■ ■ ■ ■ ■ Excellent

Product Data Sheet



Technical data

Profile		Blockprofil
Wheel Ø		260 mm (D)
Tyre width		85 mm (T2)
Tyre dimension		3.00-4
Ply rating		2
Load cap. at 4 km/h		150 kg
Tyre pressure		2,0/30 bar/psi
Axle bore Ø		20 mm (d)
Hub length		75 mm (T1)
Profile ribbed profile		B02
unit weight		1,4 kg
Temperature resistance		-25 ° C
Temperature resistance to		50 ° C
tread and tyre hardness		65° Shore A
Bearing type		Roller bearing

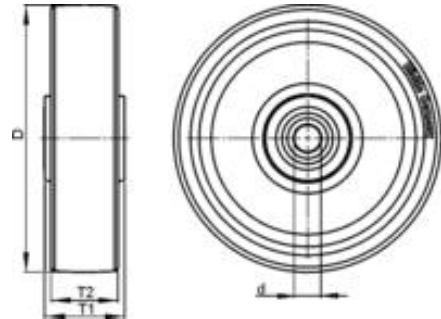

Product Data Sheet



Variants



P 263/20-75R-SG

Wheel with pneumatic tyres, with pressed steel rim