

# Product Data Sheet



## P 267/25-75K

EAN 4047526254780

ID 254789

### Wheel with pneumatic tyres, with pressed steel rim

#### Wheels:

Pneumatic tyre with tube, outstandingly high operational comfort, exceptionally high floor preservation, PAH conform acc. to EU directive 2005/69/EC.

**Tread colours:** black

#### Wheel centre/rim:

Made of pressed steel, with tubular steel hub, zinc-plated, blue-passivated, Cr6-free. Tyre mounted on rim.

**Wheel centre colour:** silver



#### Rolling resistance

■ ■ ■ □ □ Good

#### Operating noise

■ ■ ■ ■ ■ Excellent

#### Floor surface preservation


■ ■ ■ ■ ■ Excellent

# Product Data Sheet



## Technical data

Profile		Blockprofil
Wheel Ø		260 mm (D)
Tyre width		85 mm (T2)
Tyre dimension		3.00-4
Ply rating		4
Load cap. at 4 km/h		250 kg
Tyre pressure		3,5/50 bar/psi
Axle bore Ø		25 mm (d)
Hub length		75 mm (T1)
Profile ribbed profile		B02
unit weight		2,2 kg
Temperature resistance		-25 ° C
Temperature resistance to		50 ° C
tread and tyre hardness		65° Shore A
Bearing type		Ball bearing

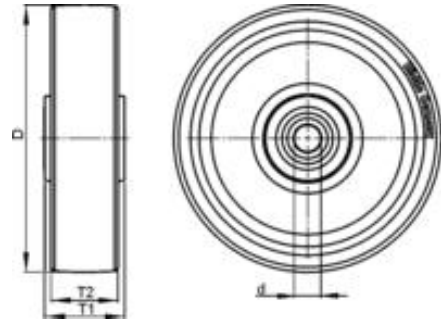

# Product Data Sheet



## Variants



### **P 267/25-75K-SG**

Wheel with pneumatic tyres, with pressed steel rim