


Pistol Grip Grease Guns

G5

G4PST

G5PRO

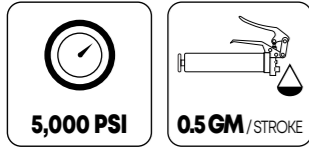

Most popular One Hand Operated Grease Gun

Designed for use in confined spaces where access to grease nipple is restricted

Built Tough

- Barrel with 0.049" (1.2 mm) wall thickness
- Heavy duty follower spring
- High tolerance CNC machined head
- Rolled threads for quick & easy re-loading

Super strong pistol grip handle designed to prevent 'pinching'

Available in 2 choices


- 4" (100 mm) steel extension & coupler
- 12" (300 mm) x 0.33" (8.5 mm) flexible hose & coupler



SPECIFICATIONS

| | | |
|----------|----------------------------------|-----------------------------|
| DEVELOPS | UPTO 5,000 PSI | UPTO 345 BAR |
| DELIVERS | UPTO 0.70 OZ. / 40 STROKES | UPTO 0.50 GM / STROKE |

FILLING OPTIONS

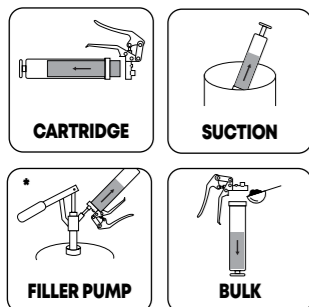

*Only G5-PRO

VARIANTS

| | | | |
|--------|--|---------------------------|--|
| G5 | | ∅ 2-1/4" (57.15 mm) | Use with 14 oz. (400 gms) grease cartridge/500cc bulk fill |
| G4-PST | | ∅ 63.5 mm | Use with 450 gms grease cartridge popular in Australia & New Zealand |
| G5-PRO | | ∅ 2-1/4" (57.15 mm) | Professional Model: Head fitted with bulk loader & air bleeder valve. Vinyl grip on movable handle Use with 14 oz. (400 gms) grease cartridge/500cc bulk fill |

ORDERING INFORMATION

| CAT NR. | ORD NR. | CAT NR. | ORD NR. | CARTRIDGE CAPACITY | | BULK CAPACITY (CM ³) | THREADS | BOX QTY. |
|---------------------------------------|---------|--------------------------------------|---------|--------------------|-------|----------------------------------|-----------|----------|
| | | | | (OZ.) | (GMS) | | | |
| 4" (100 MM) STEEL EXTENSION & COUPLER | | 12" (300 MM) FLEXIBLE HOSE & COUPLER | | | | | | |
| G5R/B | 43000 | G5F/B | 43020 | 14 | 400 | 500 | 1/8" BSPT | 16 |
| G5R/M | 43001 | G5F/M | 43021 | 14 | 400 | 500 | M10 x 1 | 16 |
| *G5R/N | 43002 | *G5F/N | 43022 | 14 | 400 | 500 | 1/8" NPT | 16 |
| *G4R/PST/B | 43080 | *G4F/PST/B | 43085 | - | 450 | 650 | 1/8" BSPT | 16 |
| G5R/PRO/B | 43050 | G5F/PRO/B | 43070 | 14 | 400 | 500 | 1/8" BSPT | 16 |
| G5R/PRO/M | 43051 | G5F/PRO/M | 43071 | 14 | 400 | 500 | M10 x 1 | 16 |
| G5R/PRO/N | 43052 | *G5F/PRO/N | 43072 | 14 | 400 | 500 | 1/8" NPT | 16 |

* Best Seller