


Lever Grease Guns Standard

G1STD **G1DC**
G23

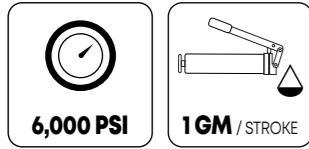

Hard working entry level grease gun, designed for general lubrication & daily maintenance jobs

Head with single vent hole fitted with a block nut

Air release achieved through half turn of head assembly

Available in 2 choices


- a. 6" (150 mm) steel extension & coupler
- b. 12" (300 mm) x 0.33" (8.5 mm) flexible hose & coupler

SPECIFICATIONS

DEVELOPS	UPTO 6,000 PSI	UPTO 413 BAR
DELIVERS	UPTO 1 OZ. / 28 STROKES	UPTO 1 GM / STROKE



FILLING OPTIONS

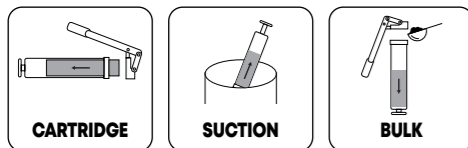

VARIANTS

G1-STD		2-1/4" (57.15 mm)	Powder coated steel head Use with 14oz. (400 gm) grease cartridge or 500cc bulk grease
G1-DC		2-1/4" (57.15 mm)	Aluminium die cast head Use with 14 oz. (400 gm) grease cartridge or 500cc bulk grease
G23		2-1/4" (57.15 mm)	Powder coated Aluminium die cast head & heavy duty lever handle Use with 14 oz. (400 gms) grease cartridge or 500 cc bulk grease

ORDERING INFORMATION

CAT NR.	ORD NR.	CAT NR.	ORD NR.	CARTRIDGE CAPACITY		BULK CAPACITY (CM ³)	THREADS	BOX QTY.
				(OZ.)	(GMS)			
6" (150 MM) STEEL EXTENSION & COUPLER		12" (300 MM) FLEXIBLE HOSE & COUPLER						
STEEL HEAD								
G1R/STD/B	42400	G1F/STD/B	42420	14	400	500	1/8" BSPT	16
G1R/STD/M	42401	G1F/STD/M	42421	14	400	500	M10 x 1	16
*G1R/STD/N	42402	G1F/STD/N	42422	14	400	500	1/8" NPT	16
ALUMINUM DIE CAST HEAD								
G1R/STD/DC/B	42450	G1F/STD/DC/B	42470	14	400	500	1/8" BSPT	16
*G1R/STD/DC/M	42451	*G1F/STD/DC/M	42471	14	400	500	M10 x 1	16
*G1R/STD/DC/N	42452	G1F/STD/DC/N	42472	14	400	500	1/8" NPT	16
POWDER COATED ALUMINUM DIE CAST HEAD								
G23R/B	42430	G23F/B	42440	14	400	500	1/8" BSPT	10
G23R/M	42431	G23F/M	42441	14	400	500	M10 x 1	10
*G23R/N	42432	G23F/N	42442	14	400	500	1/8" NPT	10

* Best Seller