


Slim Swivel Coupler 360°

HCSW11

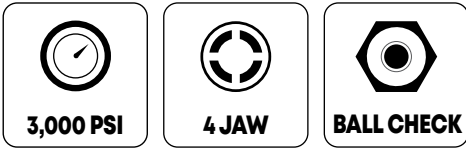

Designed for convenient access into narrow, inaccessible greasing joints

Swivels in full 360° circle & locks conveniently at any 45° position. 45° angle gives easy access to most grease fittings

Spring steel jaws are fully hardened for extended service life

Spring loaded ball check valve helps retain pressure

Zinc plated finish

For hand operated grease gun only

SPECIFICATIONS

PRESSURE	UPTO 3,000 PSI	UPTO 207 BAR
----------	-------------------	-----------------



ORDERING INFORMATION

CAT NR.	ORD NR.	THREADS
HC/SW/11/4/B	43533	1/8" BSPT
HC/SW/11/4/M	43534	M10 x 1
HC/SW/11/4/N	43538	1/8" NPT



Convenient access into narrow, inaccessible greasing joints